


Mechanic's Starter Set Industrial

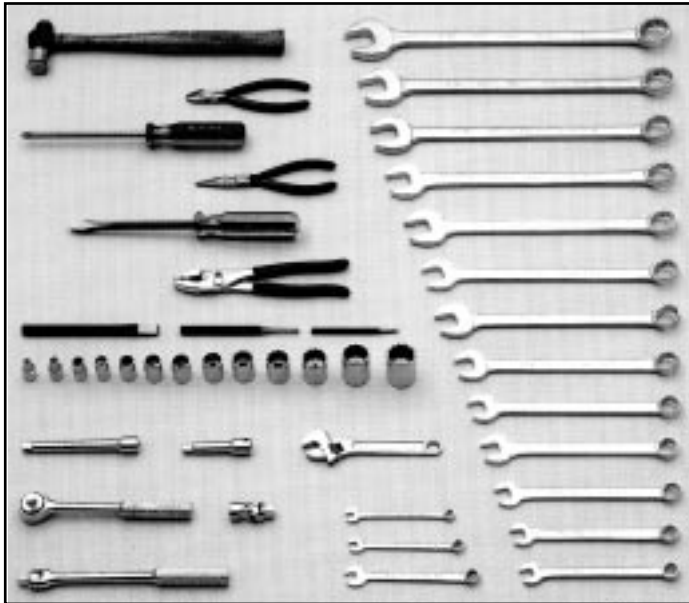

TOOL BOXBX24




M46K	
ADJUSTABLE WRENCHES	
6"	A6
COMBINATION WRENCH SET	
1/4"	1158
5/16"	1159
3/8"	1160
7/16"	1161
1/2"	1162
9/16"	1163
5/8"	1164
11/16"	1165
3/4"	1166
13/16"	1167A
7/8"	1167
Kit Bag	C110
Kit Bag	C55
15/16"	1168
1"	1170
1 1/16"	1171
1 1/8"	1172
1 1/4"	1173
3/8" DRIVE SOCKET SET	
1/4"	B1208
5/16"	B1210
3/8"	B1212
7/16"	B1214
1/2"	B1216
9/16"	B1218
5/8"	B1220
11/16"	B1222
3/4"	B1224
13/16"	B1226
7/8"	B1228
15/16"	B1230
1"	B1232
7" Rev. Ratchet	B52
3" Ext.	B103
6" Ext.	B105
Universal	B140A
Flex Handle	B40A
HAMMERS	
12 oz. Ball Peen	104G
CHISEL & PUNCH	
3/16" Pin Punch	P6
1/4" Center Punch	P38
1/2" Cold Chisel	C16
PLIERS & SCREWDRIVERS	
8" Combination Slip Joint Pliers	P208
6" Diagonal Cutting Pliers	P206
6 1/2" Long Chain Nose Side Cutting Pliers	P506
6" Square Blade Screwdriver	SDS6
6" No. 3 Phillips Screwdriver	SDP6

M46KM	
ADJUSTABLE WRENCHES	
6"	A6
COMBINATION WRENCH SET	
7 mm	1107MM
8 mm	1108MM
9 mm	1109MM
10 mm	1110MM
11 mm	1111MM
12 mm	1112MM
13 mm	1113MM
14 mm	1114MM
15 mm	1115MM
16 mm	1116MM
17 mm	1117MM
Kit Bag	C110
Kit Bag	C55
24 mm	1124MM
26 mm	1126MM
28 mm	1128MM
29 mm	1129MM
30 mm	1130MM
3/8" DRIVE SOCKET SET	
8 mm	BM1208
9 mm	BM1209
10 mm	BM1210
11 mm	BM1211
12 mm	BM1212
13 mm	BM1213
14 mm	BM1214
15 mm	BM1215
16 mm	BM1216
17 mm	BM1217
18 mm	BM1218
19 mm	BM1219
Adaptor	BS130
7" Rev. Ratchet	B52
3" Ext.	B103
6" Ext.	B105
Universal	B140A
Flex Handle	B40A
HAMMERS	
12 oz. Ball Peen	104G
CHISEL & PUNCH	
3/16" Pin Punch	P6
1/4" Center Punch	P38
1/2" Cold Chisel	C16
PLIERS & SCREWDRIVERS	
8" Combination Slip Joint Pliers	P208
6" Diagonal Cutting Pliers	P206
6 1/2" Long Chain Nose Side Cutting Pliers	P506
6" Square Blade Screwdriver	SDS6
6" No. 3 Phillips Screwdriver	SDP6

Martin

Mechanic's Set Industrial

TOOL BOXBX26

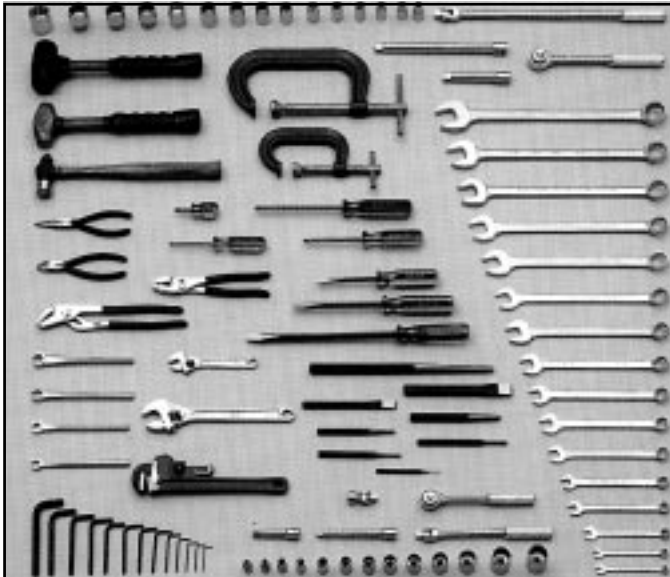

M100K

3/8" DRIVE SOCKET SET	
1/4".....B1208	13/16".....B1226
5/16".....B1210	7/8".....B1228
3/8".....B1212	15/16".....B1230
7/16".....B1214	1".....B1232
1/2".....B1216	3" Ext.....B103
9/16".....B1218	6" Ext.....B105
5/8".....B1220	Flex Handle.....B40A
11/16".....B1222	Universal Joint.....B140A
3/4".....B1224	7" Rev. Ratchet.....B52
1/2" DRIVE SOCKET SET	
3/8".....ST1212	1".....ST1232
7/16".....ST1214	1 1/8".....ST1234
1/2".....ST1216	1 1/4".....ST1236
9/16".....ST1218	1 3/8".....ST1238
5/8".....ST1220	1 1/2".....ST1240
11/16".....ST1222	5" Ext.....S110P
3/4".....ST1224	10" Ext.....S115P
13/16".....ST1226	Flex Handle.....SF41
7/8".....ST1228	Rev. Ratchet.....SF51
15/16".....ST1230	
COMBINATION WRENCHES	
1/4".....1158	5/16".....1168
5/16".....1159	1".....1170
3/8".....1160	1 1/8".....1171
7/16".....1161	1 1/4".....1172
1/2".....1162	1 3/8".....1173
9/16".....1163	Kit Bag.....C55
5/8".....1164	
11/16".....1165	FLARE NUT WRENCHES
3/4".....1166	7/8".....4112
13/16".....1167A	1".....4114
7/8".....1167	1 1/8".....4116
Kit Bag.....C110	9/16".....4118
C-CLAMPS	
0-3.....CC403	
0-6 1/16.....CC406	
HAMMERS	
12 oz.....104G	
1.50 lbs.....HSB15	
1.25 lbs.....HPD 1	
CHISEL & PUNCH	
3/16" Pin.....P6	
3/16" Center.....P40	
1/2" Cold.....C16	
1/4" Pin.....P8	
1/4" Center.....P42	
3/4" Cold.....C24	
1/16" Pin.....P2	
1/4" Taper.....P27	
SCREWDRIVERS & PLIERS	
8" Combo.....P208	
6" Diagonal.....P206	
6 1/2" Chain Nose.....P506	
10" Groove.....P510	
4" Square Blade.....SDS4	
6" Square Blade.....SDS6	
10" Square Blade.....SDS10	
3" Phillips No. 1.....SDP3	
4" Phillips No. 2.....SDP4	
6" Phillips No. 3.....SDP6	
1 1/2" Stubby No. 2.....SDP1	
HEX KEY WRENCH SET	
13 pcs. Short Arm Series...13S	
ADJUSTABLE & PIPE WRENCHES	
6".....A6	
10".....A10	
10".....PW10	

M100KM

3/8" DRIVE SOCKET SET	
8 mm.....BM1208	17mm.....BM1217
9 mm.....BM1209	18 mm.....BM1218
10 mm.....BM1210	19 mm.....BM1219
11 mm.....BM1211	Adaptor.....BS130
12 mm.....BM1212	3" Ext.....B103
13 mm.....BM1213	5" Ext.....B105
14 mm.....BM1214	Flex Handle.....B40A
15 mm.....BM1215	Universal Joint.....B140A
16 mm.....BM1216	7" Rev. Ratchet.....B52
1/2" DRIVE SOCKET SET	
10 mm.....STM1210	25 mm.....STM1225
11 mm.....STM1211	26 mm.....STM1226
12 mm.....STM1212	27 mm.....STM1227
13 mm.....STM1213	30 mm.....STM1230
14 mm.....STM1215	32 mm.....STM1232
17 mm.....STM1217	5" Ext.....S110P
19 mm.....STM1219	10" Ext.....S115P
22 mm.....STM1222	Flex Handle.....SF41
23 mm.....STM1223	Rev. Ratchet.....SF51
24 mm.....STM1224	
COMBINATION WRENCHES	
7 mm.....1107MM	24 mm.....1124MM
8 mm.....1108MM	26 mm.....1126MM
9 mm.....1109MM	28 mm.....1128MM
10 mm.....1110MM	29 mm.....1129MM
11 mm.....1111MM	30 mm.....1130MM
12 mm.....1112MM	Kit Bag.....C55
13 mm.....1113MM	
14 mm.....1114MM	FLARE NUT WRENCHES
15 mm.....1115MM	3/8".....4112
16 mm.....1116MM	7/16".....4114
17 mm.....1117MM	1/2".....4116
Kit Bag.....C110	9/16".....4118
C-CLAMPS	
0-3.....CC403	
0-6 1/16.....CC406	
HAMMERS	
12 oz.....104G	
1.50 lbs.....HSB15	
1.25 lbs.....HPD 1	
CHISEL & PUNCH	
3/16" Pin.....P6	
3/16" Center.....P40	
1/2" Cold.....C16	
1/4" Pin.....P8	
1/4" Center.....P42	
3/4" Cold.....C24	
1/16" Pin.....P2	
1/4" Taper.....P27	
PLIERS & SCREWDRIVERS	
8" Combo.....P208	
6" Diagonal.....P206	
6 1/2" Chain Nose.....P506	
10" Groove.....P510	
4" Square Blade.....SDS4	
6" Square Blade.....SDS6	
10" Square Blade.....SDS10	
3" Phillips No. 1.....SDP3	
4" Phillips No. 2.....SDP4	
6" Phillips No. 3.....SDP6	
1 1/2" Stubby No. 2.....SDP1	
HEX KEY WRENCH SET	
13 pcs. Short Arm Series...13S	
ADJUSTABLE & PIPE WRENCHES	
6".....A6	
10".....A10	
10".....PW10	