


Martin

Spanner Wrench

Manufacturing Quality Hand Tools Since 1917

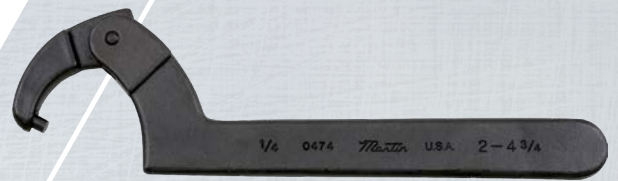

Adjustable Pin Spanner



Adjustable Hook Spanner



Adjustable Face Spanner



Fixed Pin Spanner



Fixed Face Spanner

- **Spanner wrenches** cover several nut sizes. The pins or hook fit into the holes or slots on the side of the flange or collar. Spanner Wrenches are often used to tighten shafts or pipes.
- **Adjustable Opening** - These are special purpose wrenches with an adjustable opening feature designed for servicing packing glands, adjustable collars, rings, locknuts, and more.
- **All Spanner Wrenches are Drop forged from USA steel**

Available Sets



SHW5K



SPW6K

*Made with USA Steel
Manufactured in the USA*

martinsprocket.com • 817.258.3000

 







Adjustable Spanner Wrench

Quick Reference Guide

Pins fit into the holes or slots on the side of the flange or collar.

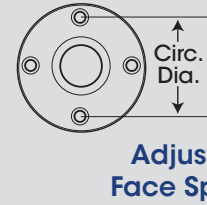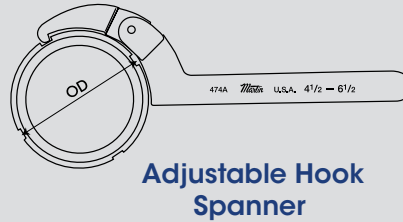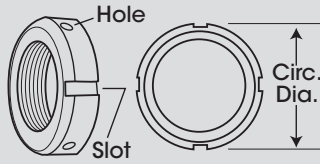

Pin Spanner

Part Number	For Circle Diameter	Diameter of Pin	Length of Pin	Overall Length
452	1	3/16	3/16	4
453	1-1/4	13/64	3/16	4-1/2
454	1-1/2	7/32	7/32	5
455	1-3/4	15/64	7/32	5-1/2
456	2	1/4	1/4	6
457	2-1/4	17/64	1/4	6-1/2
458	2-1/2	9/32	9/32	7
459	2-3/4	19/64	9/32	7-1/2
460	3	5/16	5/16	8
461	3-1/4	21/64	5/16	8-1/2
462	3-1/2	11/32	11/32	9
463	3-3/4	23/64	11/32	9-1/2
464	4	3/8	3/8	10
466	5	7/16	7/16	12
468	6	1/2	1/2	14

Face Spanner

Part Number	Center Distance of Pins	Pins		Span of Jaws in Clear	Length from Center of Pins	Thickness
		Diameter	Length			
418	1	3/16	3/16	11/16	4-1/2	3/16
420	1-1/4	7/32	7/32	7/8	5	3/16
422	1-1/2	7/32	7/32	1-1/8	5-1/2	3/16
424	1-3/4	7/32	7/32	1-3/8	6	7/32
426	2	1/4	1/4	1-19/32	6-1/2	7/32
428	2-1/4	1/4	1/4	1-27/32	7	7/32
430	2-1/2	9/32	9/32	2-1/32	7-1/2	1/4
432	2-3/4	9/32	9/32	2-9/32	8	1/4
434	3	5/16	5/16	2-1/2	8-1/2	1/4
436	3-1/4	5/16	5/16	2-3/4	9-1/8	1/4
438	3-1/2	5/16	5/16	3	9-3/4	1/4
440	3-3/4	3/8	3/8	3-3/16	10-3/8	1/4
442	4	3/8	3/8	3-7/16	11	1/4



Adjustable Face Spanner

Part Number	Extreme Capacity	Diameter of Pin	Length of Pin	Overall Length
482	2	3/16	7/32	6-1/4
483	3	1/4	9/32	8-1/4
484	4	5/16	11/32	10-1/4

Adjustable Hook Spanner

Part Number	Capacity Range	Thickness of Handle	Thickness of Hook	Depth of Hook	Overall Length
471	3/4 to 2	1/4	3/8	1/8	6-1/2
472	1-1/4 to 3	9/32	1/2	5/32	8-1/16
474	2 to 4-3/4	11/32	17/32	7/32	11-3/16
474A	4-1/2 to 6-1/4	11/32	17/32	1/4	12
474B	6-1/8 to 8-3/4	11/32	17/32	5/16	13-5/16



Adjustable Pin Spanner

Part Number	Capacity Range	Thickness		Pin Size		Overall Length
		Handle	Hook	Diameter	Length	
0471	3/4 to 2	1/4	3/8	1/8	1/8	6-1/2
0471A	3/4 to 2	1/4	3/8	3/16	5/32	6-1/2
0472	1-1/4 to 3	9/32	1/2	3/16	3/16	8-1/16
0472A	1-1/4 to 3	9/32	1/2	1/4	7/32	8-1/16
0474	2 to 4-3/4	11/32	17/32	1/4	1/4	11-3/16
0474A	4-1/2 to 6-1/4	11/32	17/32	3/8	1/4	12-3/16